


MCRK-8-S

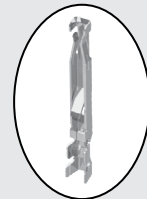

CC393-2830-L-S

MCRK, CC393 SERIES

8 SERIES IP67 FIELD TERMINATION KIT


Mates with:
MCP(K)

SPECIFICATIONS

For complete specifications see www.samtec.com?MCRK

- Insulator Material:**
PPS
- Contact Material:**
Phosphor Bronze
- Operating Temp Range:**
-20 °C to +80 °C
- Gasket Material:**
Neoprene Rubber
- Lock Washer:**
Phosphor Bronze, Ni plated
- Hex Nut:**
Brass, Ni plated
- RoHS Compliant:**
Yes

PANEL OPENING

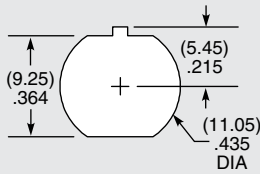


Note: Samtec's MCRK Series is dual sourced by Hirose Electric Co., LTD.



DUST CAPS

- DCA-MCR-8
- Visit sealedio.samtec.com for a complete list of sealed systems

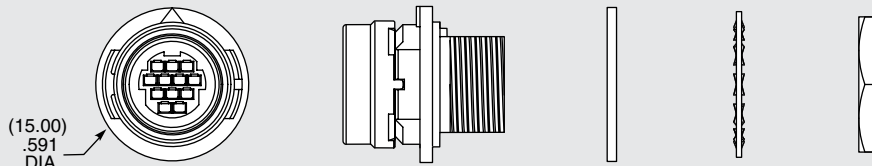

SPECIFICATIONS

For complete specifications see www.samtec.com?CC393

Plating:
10 μm (0.25 μm) Gold on contact

TOOLING

- Hand Tool:
CAT-HT-393-2430-13
- Mini Applicator
(28-30 AWG):
CAT-MC-393-2830-XX-01
- Extraction Tool:
CAT-EX-MCX-8-01

