

(2,00 mm) .0787"

ETMM, TLMM SERIES

ETMM-108-02-F-D-TH-LC

TLMM-125-01-L-D-SM-K

ETMM-112-02-F-D-RA

SHROUDED STRAIN RELIEF IDC HEADER

SPECIFICATIONS

For complete specifications
see www.samtec.com?ETMM
or www.samtec.com?TLMM

Insulator Material:

Black Liquid Crystal
Polymer (ETMM)

High Temp Nylon (TLMM)

Terminal Material:

Phosphor Bronze

Plating:

Sn or Au over
50µ" (1,27 µm) Ni

Current Rating:

3A per contact
@ 80°C ambient

Operating Temp Range:

-55°C to +125°C

RoHS Compliant:

Yes

Processing:

Lead-Free Solderable:

Yes

SMT Lead Coplanarity:

(0,13 mm) .005" max

RoHS Compliant:

Yes

Mates with:
TLSD, TCSD, TCMD

ALSO AVAILABLE

Contact Samtec for other sizes.


See STMM Series for TCSD
mates without Strain Relief.

See LTMM for shrouded header
for mating with Connector Strips.

Shrouded pins
for protection

Surface Mount,
Through-hole and
Right Angle

Optional
Locking clips

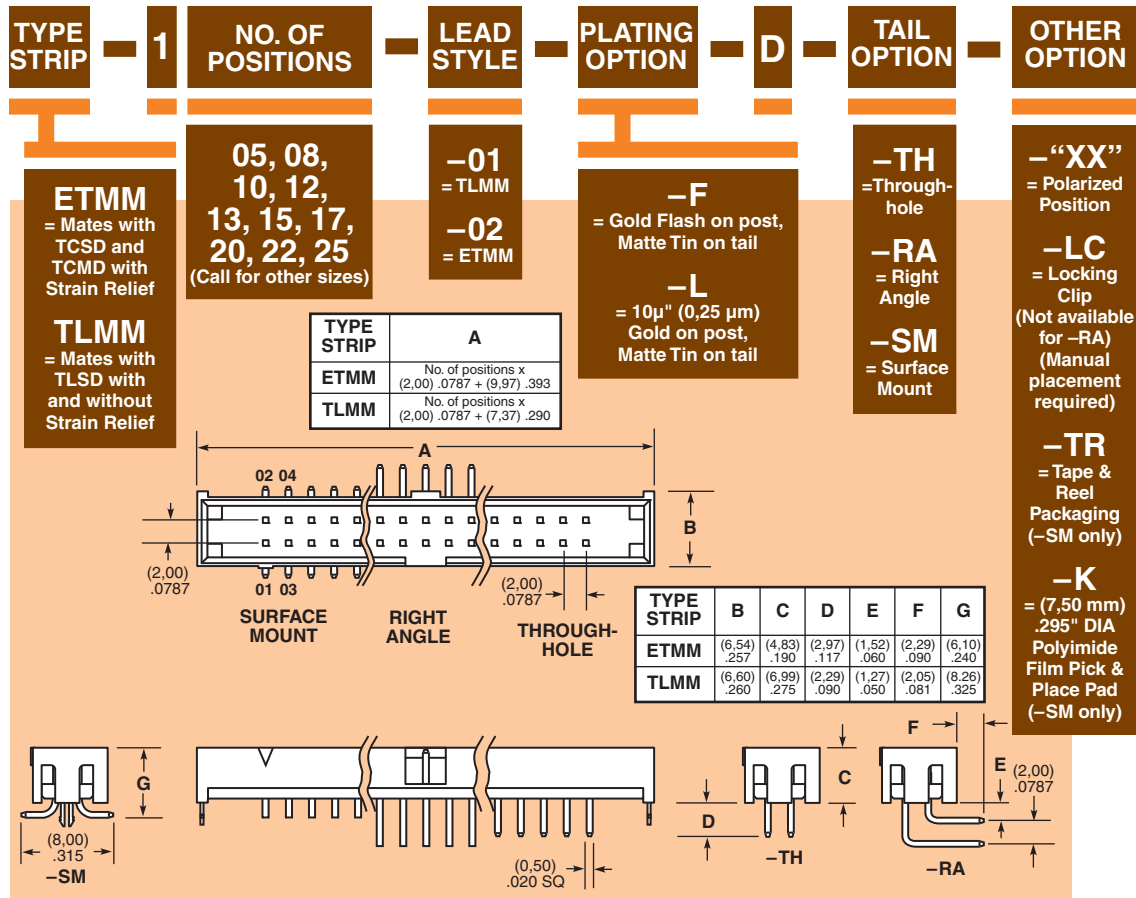

Note: Some lengths, styles and options are non-standard, non-returnable.

Due to technical progress, all designs, specifications and components are subject to change without notice.

WWW.SAMTEC.COM

SAMTEC USA • Tel: 1-800-SAMTEC-9 or 812-944-6733 SAMTEC NORTHERN CALIFORNIA • Tel: 408-395-5900 SAMTEC SOUTHERN CALIFORNIA • Tel: 1-800-726-8329
SAMTEC AMERICA LATINA COMERCIO EXTERIOR LTDA • Tel: (+55 31) 3786 3227 SAMTEC UNITED KINGDOM • Tel: 44 01236 739292 SAMTEC GERMANY • Tel: +49 (0) 89 / 89460-0
SAMTEC FRANCE • Tel: 33 01 60 95 06 60 SAMTEC ITALY • Tel: 39 039 6890337 SAMTEC NORDIC/BALTIC • Tel: +46-84477280 SAMTEC BENELUX • Tel: 44 01236 739292
SAMTEC ISRAEL • Tel: 972-3-7526600 SAMTEC INDIA • Tel: +91-80-3272 1612 SAMTEC ASIA PACIFIC • Tel: 65 6745-5955 SAMTEC JAPAN • Tel: 045-475-1385 SAMTEC CHINA • Tel: 86-21-6083 3766
SAMTEC TAIWAN • Tel: 886-2-2735-6109 SAMTEC HONG KONG • Tel: 852-26904858 SAMTEC KOREA • Tel: 82-31-717-5685 SAMTEC ANZ • Tel: 613 9580 0683