


UBPS-4-S-RA

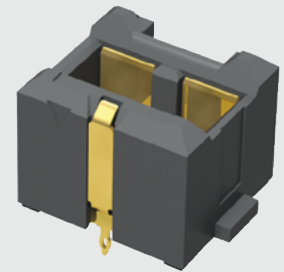

UBPT-4-01.0-S

UBPT, UBPS-RA SERIES

(1.50 mm) .059"

SEARAY™ POWER MODULES

Mates with:

UBPS
(used with SEAM8, SEAM)

SPECIFICATIONS

For complete specifications and recommended PCB layouts see www.samtec.com?UBPT

Current Rating:
20 A per module

RECOGNITIONS

For complete scope of recognitions see www.samtec.com/quality



Note:
Some lengths, styles and options are non-standard, non-returnable.

UBPT	NO. OF POSITIONS	LEAD STYLE	PLATING OPTION
	-4 = 4 positions (Total 2 per row)	-01.0 = Extended	-S = 30 μ" (0.76 μm) Gold on contact, Matte Tin on tail

APPLICATION

Mates with:

UBPS
(used with SEAF8, SEAF)

SPECIFICATIONS

For complete specifications and recommended PCB layouts see www.samtec.com?UBPS-RA

Current Rating:
20 A per module

RECOGNITIONS

For complete scope of recognitions see www.samtec.com/quality



Note:
Some lengths, styles and options are non-standard, non-returnable.

UBPS	NO. OF POSITIONS	PLATING OPTION	RA
	-4 = 4 positions (Total 2 per row)	-S = 30 μ" (0.76 μm) Gold on contact, Matte Tin on tail	-RA = Right-angle

Due to technical progress, all designs, specifications and components are subject to change without notice.