




.047, HIGH-FREQUENCY CABLE ASSEMBLY

TO 67 GHz, FLEXIBLE LOW-LOSS CABLE

RF047-A SERIES, FEATURES & BENEFITS

- Low VSWR and Low Insertion Loss
- High Flexibility (semi-rigid alternative)
- Multiple cable connector options – 1.85 mm, 2.40 mm, 2.92 mm and SMPM
- Custom cable connector options available
- 40 GHz, 50 GHz and 67 GHz performance (dependent on cable connector option)
- 50 Ohm solution

DC TO
67
GHz

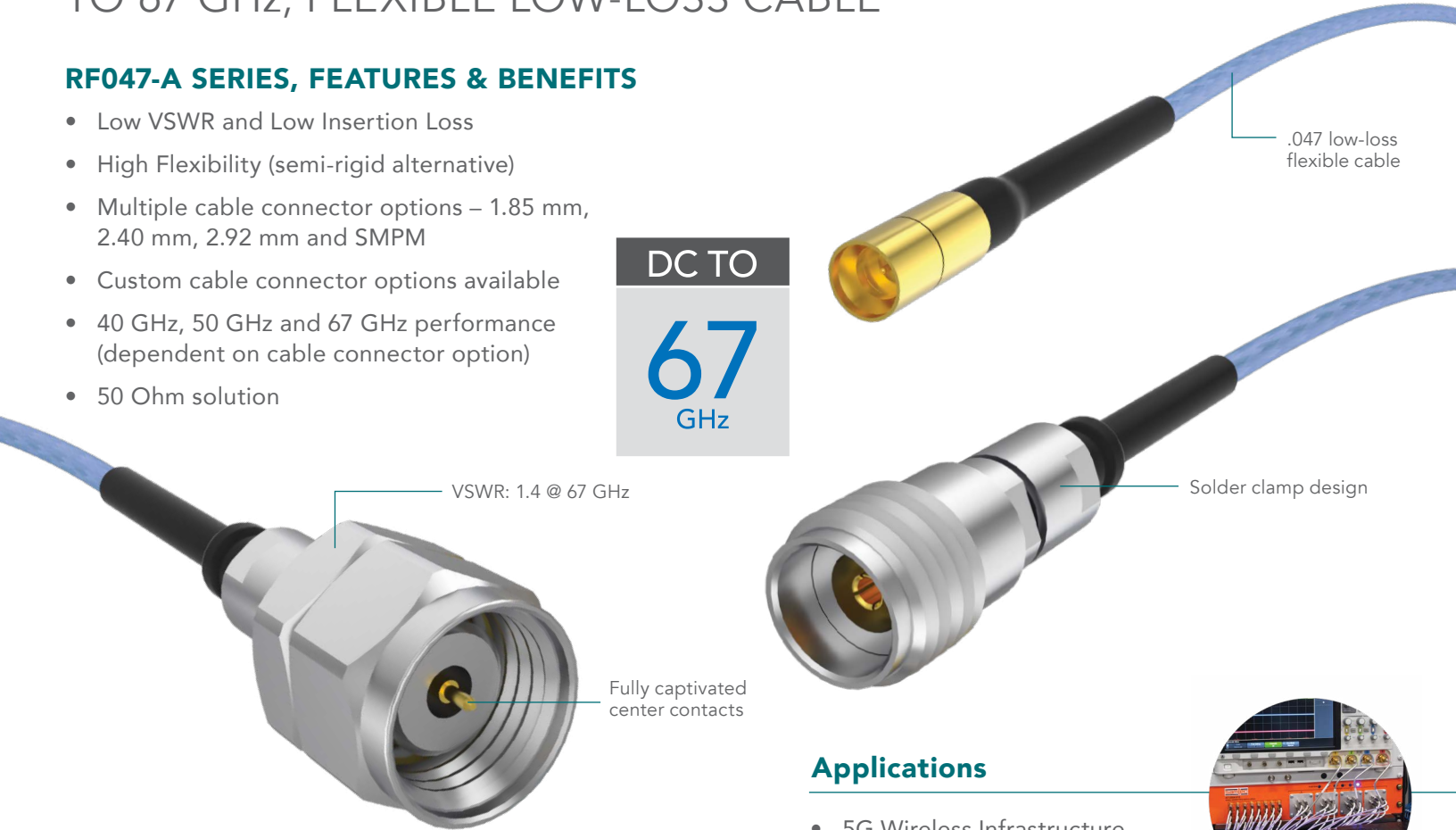

CABLE CONNECTOR OPTIONS			
Threaded			Push-On
1.85 mm jack	2.40 mm jack	2.92 mm jack	SMPM jack
1.85 mm plug	2.40 mm plug	2.92 mm plug	SMPM plug

Applications

- 5G Wireless Infrastructure
- Defense, Aerospace and Telecom
- RF Test & Measurement
- Applications that are space limited and/or requiring flexibility

