
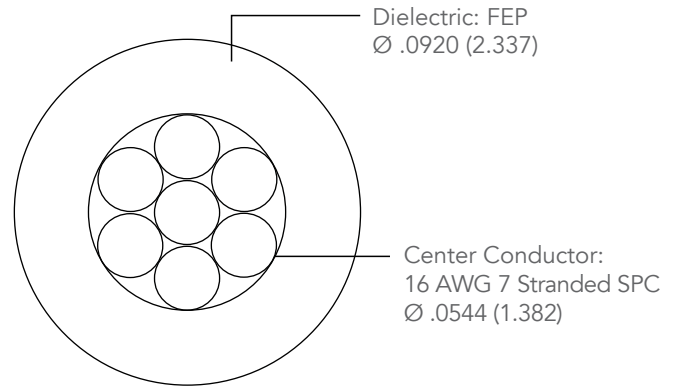


16 AWG POWER CABLE HT

DWCT-16-01-600

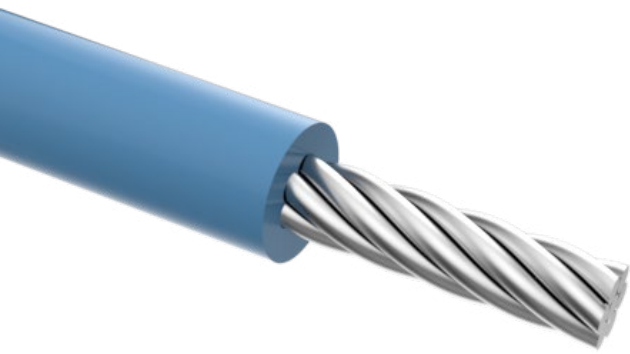


PERFORMANCE DATA

Flex Cycles:	7,500 cycles*
Current Rating:	Single Powerline = 15.5 Amps**
Voltage Rating:	600 V***
CC DCR:	4.35 Ω/1000 ft
Availability:	Single, tape bonded
Temperature Rating:	-10 °C to 200 °C, UL VW-1 Rated *** -40 °C to 200 °C****
DWV Working Voltage:	1250 V†

* Test Conditions – 4 oz. weight, dia 1/4" mandrel, +/-90 bend X2
 ** Rating – 30 °C Temperature Rise, 20% de-rated.
 *** Test Conditions - U.L certification under style #10970 in file E321359, 600 V, 60 C oil resistance, horizontal and VW-1 flame rating
 **** Test Conditions – Heat Shock/Cold Bend per UL #1581, wire wrap 1/4" mandrel, visual inspection
 † Test Conditions – DWV per EIA-364-20, ASTM D470-13 and D149-09

CURRENT CARRYING CAPACITY GRAPHS **

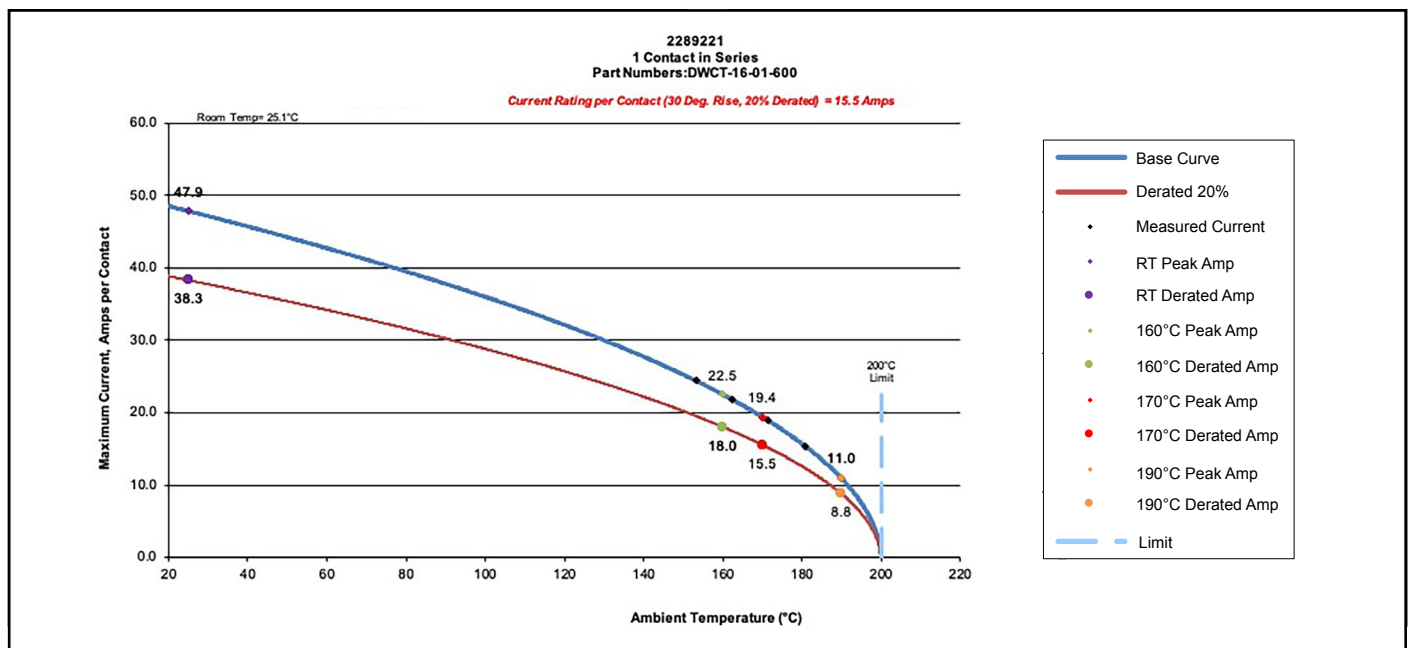

1.800.SAMTEC.9 • HDR@samtec.com