
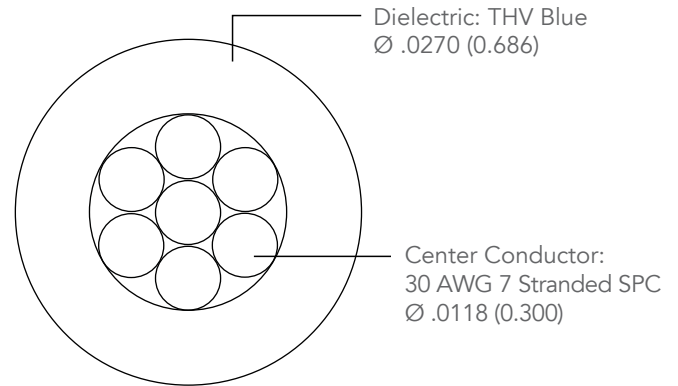


30 AWG POWER CABLE HT-THV

SPL-30-XX-XX

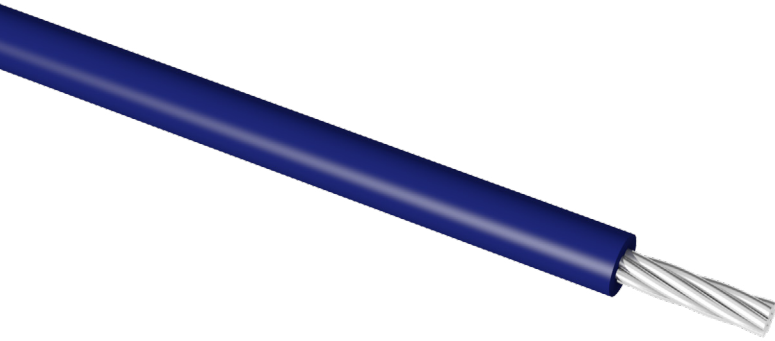

PERFORMANCE DATA

Flex Cycles:	8,000 cycles, 20-wide ribbon*
Current Rating:	Single = 3.0 Amps** 5-wide ribbon = 1.6 Amps**
CC DCR:	101 Ω/1000 ft
Availability:	Single, 2-30 ribbon, tape bonded
Temperature Rating:	-40 °C to 125 °C ***
Flammability Rating:	UL VW-1†
DWV Working Voltage:	1250 V‡

* Test Conditions – 8 oz. weight, dia 1/4" mandrel, +/-90 bend X2



** Rating – 30 °C Temperature Rise, 20% de-rated.
Testing performed on 20-position ribbon.

*** Test Conditions – Heat Shock/Cold Bend per UL #1581-540 and #1581-580,
wire wrap 1/4" mandrel, visual inspection

†SPL-30-02 and SPL-30-T02 have undergone UL VW-1 Research Testing and
comply with UL 758.

‡Test Conditions – DWV per EIA-364-20, ASTM D470-13 and D149-09

CURRENT CARRYING CAPACITY GRAPHS **

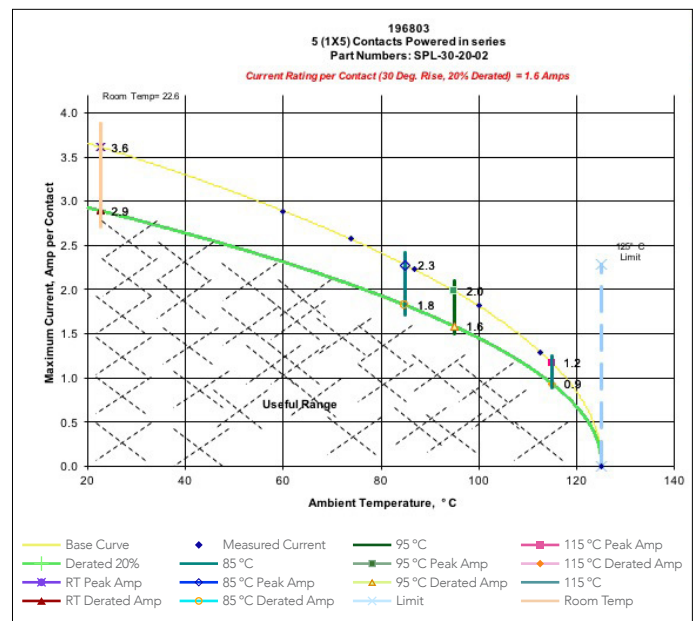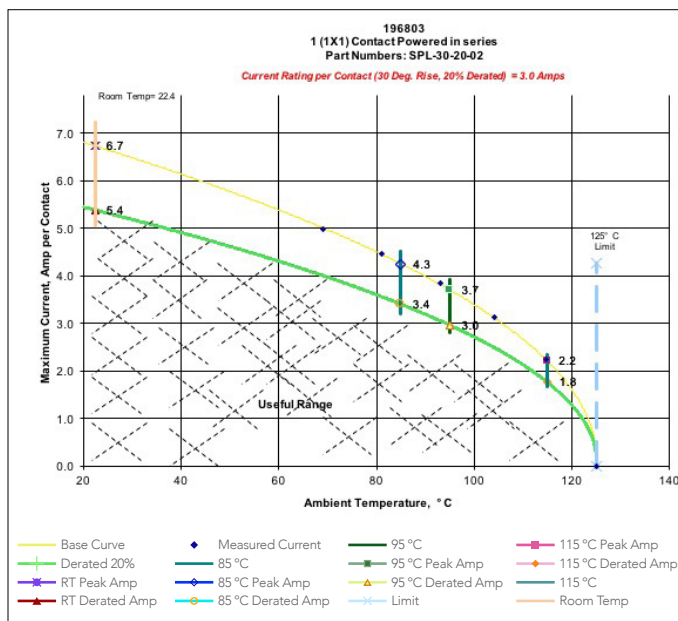

samtec

1.800.SAMTEC.9 • HDR@samtec.com

June 26, 2023 • Rev: F