


Series: QRM8-DP / QRF8-DP Series

Description: 0.8 mm Q Rate® High-Speed Ground Plane, Slim Body, Differential Pair, 10mm Stack Height

Time Domain Data Summary

Signal Risetime	30ps	50ps	100ps	250ps	500ps
Maximum Impedance	100.8	100.0	100.1	99.6	98.8
Minimum Impedance	81.7	84.5	89.9	94.3	97.0

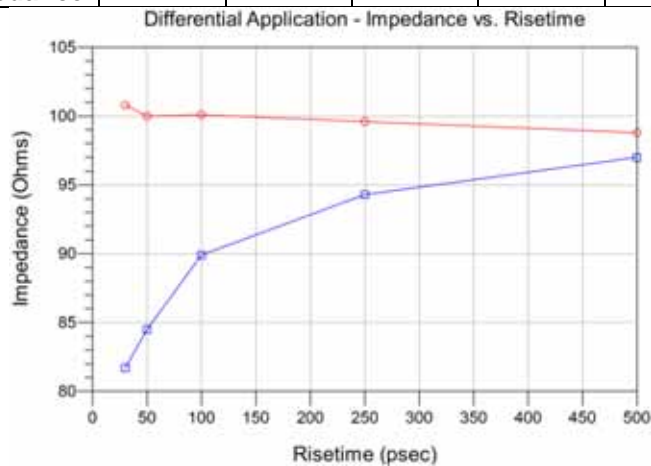

Input(t_r)		Driver	Receiver	30ps	50ps	100ps	250ps	500ps
NEXT	GAAQQG	QRM8_25,27	QRM8_29,31	1.75	1.52	1.23	0.67	0.37
	Xrow	QRM8_25,27	QRM8_26,28	0.17	0.11	<0.1	<0.1	<0.1
FEXT	GAAQQG	QRM8_25,27	QRF8_29,31	0.85	0.45	0.18	<0.1	<0.1
	Xrow	QRM8_25,27	QRF8_26,28	0.18	0.13	<0.1	<0.1	<0.1

Differential	63 ps
---------------------	-------